


Switched Rack PDU

Outlets. The Rack PDU has twenty-four (24) NEMA 5-20 outlets.

Display interface. The interface uses a digital display that shows aggregate current being used by the PDU.

Power cord. The 10-foot (3.05-meter) power cord terminates with a NEMA L5-30 connector.

AS-024-520-30A-L530

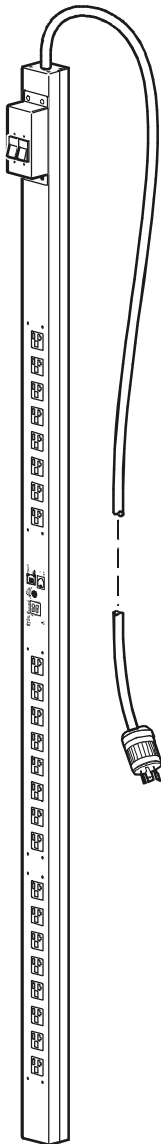

Specifications

Electrical

Input connector	NEMA L5-30 plug
Output connectors	(24) NEMA 5-20 outlets
Nominal input voltage	120 VAC
Acceptable input voltage	± 10% of nominal voltage
Input frequency	50/60 Hz

Physical

Dimensions (H × W × D)	70.00 x 2.19 x 1.73 in (177.8 x 5.56 x 4.39 cm)
Shipping dimensions (H × W × D)	84.00 x 6.00 x 5.00 in (213.36 x 15.24 x 12.7 cm)
Weight	16.25 lb (7.37 kg)

Environmental

Elevation (above MSL)	
Operating	15,000 ft (4500 m)
Storage	50,000 ft (15 000 m)
Temperature	
Operating	23 to 115° F (-5 to 45° C)
Storage	-13 to 149° F (-25 to 65° C)
Humidity	
Operating	5 – 11/200895% RH Non-condensing
Storage	5 – 95% RH Non-condensing

Compliance

EMC verification	FCC Part 15 Class A ICES-003 Class A
Safety verification	UL/cUL 60950 Listed
