


LCD2U15-03/17-03/19-02 2U Dual Slide Short Depth LCD Keyboard KVM Drawer

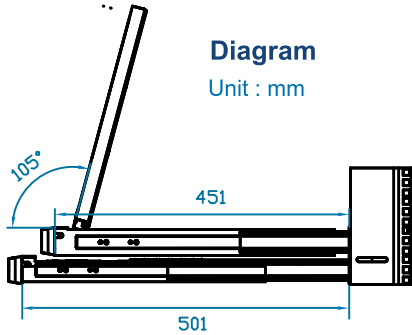

Options



BNC + S-Video



DVI-D



DC Power



Touch Screen



Audio

BNC + S-Video



Touchscreen - USB



DVI-D



Touchscreen - Serial



DC Power



Audio



****With DC power option, the depth of LCD2U15-03/17-03/19-02 will be extended from 480mm (18.9") to 530mm (20.9")**



LCD Drawer & KVM Benefits

- ▶ 2U dual slide rackmount drawer with either 15", 17" or 19" LCD
- ▶ Short depth design of 480mm (18.9") only
- ▶ Depth will suit a 600mm rack application
- ▶ Multi-user Matrix KVM with either 16 or 32 ports in 2U
- ▶ Cost efficient Combo KVM integration
- ▶ Secure remote user access across the world wide web
- ▶ "One Man" installation slides for easy, quick installation

Drawer Features & Options

- Combo interface either PS/2 or USB input to the LCD drawer
- Multiple keyboard language selections with either touchpad or trackball
- Slide rails with fixed positions to prevent drawer movement when typing
- Enhanced aesthetics with new molded front panel and two point lock

Monitor Grade A 15", 17", 19" industrial TFT LCD panel

- 15" 1024 x 768 LCD with 250 nit brightness and 700:1 contrast ratio typical
- 17" 1280 x 1024 LCD with 300 nit brightness and 1000:1 contrast ratio typical
- 19" 1280 x 1024 LCD with 300 nit brightness and 1000:1 contrast ratio typical

Dimensions


Model	Product Dimension (W x D x H)	Net Weight
LCD2U15-03/17-03	442 x 480 x 88 mm 17.4 x 18.9 x 3.5 inch	17 kg / 37 lbs
LCD2U19-02	442 x 480 x 88 mm 17.4 x 18.9 x 3.5 inch	18 kg / 40 lbs

Keyboard Selection


Supporting layouts



N 104 Keyboard integrated with touchpad

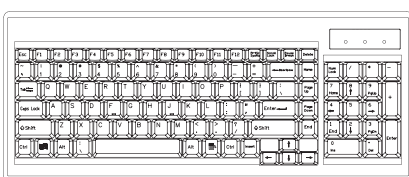

B 104 Keyboard integrated with trackball

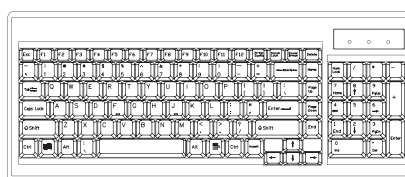

KVM Selection


Base Model

15" LCD Series

17" LCD Series

19" LCD Series

* Single port w/o KVM * Combo interface	LCD2U15-03	LCD2U17-03	LCD2U19-02
--	------------	------------	------------

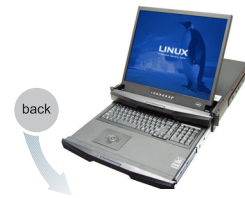







Matrix Cat6 KVM







*** No KVM membrane button will be provided for all models ***

	2 consoles	Matrix Cat6	16 port	LCD2U15-03-MU162	LCD2U17-03-MU162	LCD2U19-02-MU162
	3 consoles			LCD2U15-03-MU163	LCD2U17-03-MU163	LCD2U19-02-MU163
	4 consoles			LCD2U15-03-MU164	LCD2U17-03-MU164	LCD2U19-02-MU164
IP 	3 consoles	Matrix IP Cat6	16 port	LCD2U15-03-MU163IP	LCD2U17-03-MU163IP	LCD2U19-02-MU163IP
IP 	4 consoles			LCD2U15-03-MU164IP	LCD2U17-03-MU164IP	LCD2U19-02-MU164IP
IP IP 	4 consoles			LCD2U15-03-MU164IP2	LCD2U17-03-MU164IP2	LCD2U19-02-MU164IP2



 

 
 

 

	2 consoles	Matrix Cat6	32 port	LCD2U15-03-MU322	LCD2U17-03-MU322	LCD2U19-02-MU322
	3 consoles			LCD2U15-03-MU323	LCD2U17-03-MU323	LCD2U19-02-MU323
	4 consoles			LCD2U15-03-MU324	LCD2U17-03-MU324	LCD2U19-02-MU324
IP 	3 consoles	Matrix IP Cat6	32 port	LCD2U15-03-MU323IP	LCD2U17-03-MU323IP	LCD2U19-02-MU323IP
IP 	4 consoles			LCD2U15-03-MU324IP	LCD2U17-03-MU324IP	LCD2U19-02-MU324IP
IP IP 	4 consoles			LCD2U15-03-MU324IP2	LCD2U17-03-MU324IP2	LCD2U19-02-MU324IP2

Matrix DB-15 KVM






	2 consoles	Matrix DB-15	8 port	LCD2U15-03-M82	LCD2U17-03-M82	LCD2U19-02-M82
	3 consoles			LCD2U15-03-M83	LCD2U17-03-M83	LCD2U19-02-M83
	4 consoles			LCD2U15-03-M84	LCD2U17-03-M84	LCD2U19-02-M84
IP 	3 consoles	Matrix IP DB-15	8 port	LCD2U15-03-M83IP	LCD2U17-03-M83IP	LCD2U19-02-M83IP
IP 	4 consoles			LCD2U15-03-M84IP	LCD2U17-03-M84IP	LCD2U19-02-M84IP
IP IP 	4 consoles			LCD2U15-03-M84IP2	LCD2U17-03-M84IP2	LCD2U19-02-M84IP2

	2 consoles	Matrix DB-15	16 port	LCD2U15-03-M162	LCD2U17-03-M162	LCD2U19-02-M162
	3 consoles			LCD2U15-03-M163	LCD2U17-03-M163	LCD2U19-02-M163
	4 consoles			LCD2U15-03-M164	LCD2U17-03-M164	LCD2U19-02-M164
IP 	3 consoles	Matrix IP DB-15	16 port	LCD2U15-03-M163IP	LCD2U17-03-M163IP	LCD2U19-02-M163IP
IP 	4 consoles			LCD2U15-03-M164IP	LCD2U17-03-M164IP	LCD2U19-02-M164IP
IP IP 	4 consoles			LCD2U15-03-M164IP2	LCD2U17-03-M164IP2	LCD2U19-02-M164IP2



Combo Cat6 KVM

	1 console	Combo Cat6	8 port	LCD2U15-03-U8KVM	LCD2U17-03-U8KVM	LCD2U19-02-U8KVM
	2 consoles			LCD2U15-03-U8KVM2	LCD2U17-03-U8KVM2	LCD2U19-02-U8KVM2
IP 	2 consoles			LCD2U15-03-U8KVM2IP	LCD2U17-03-U8KVM2IP	LCD2U19-02-U8KVM2IP
	1 console	Combo Cat6	16 port	LCD2U15-03-U16KVM	LCD2U17-03-U16KVM	LCD2U19-02-U16KVM
	2 consoles			LCD2U15-03-U16KVM2	LCD2U17-03-U16KVM2	LCD2U19-02-U16KVM2
IP 	2 consoles			LCD2U15-03-U16KVM2IP	LCD2U17-03-U16KVM2IP	LCD2U19-02-U16KVM2IP
	1 console	Combo Cat6	32 port	LCD2U15-03-U32KVM	LCD2U17-03-U32KVM	LCD2U19-02-U32KVM
	2 consoles			LCD2U15-03-U32KVM2	LCD2U17-03-U32KVM2	LCD2U19-02-U32KVM2
IP 	2 consoles			LCD2U15-03-U32KVM2IP	LCD2U17-03-U32KVM2IP	LCD2U19-02-U32KVM2IP

Combo DB-15 KVM

	1 console	Combo DB-15	8 port	LCD2U15-03-8KVM-u	LCD2U17-03-8KVM-u	LCD2U19-02-8KVM-u
	2 consoles			LCD2U15-03-8KVM2	LCD2U17-03-8KVM2	LCD2U19-02-8KVM2
IP 	2 consoles			LCD2U15-03-8KVM2IP	LCD2U17-03-8KVM2IP	LCD2U19-02-8KVM2IP
	1 console	Combo DB-15	16 port	LCD2U15-03-16KVM-u	LCD2U17-03-16KVM-u	LCD2U19-02-16KVM-u
	2 consoles			LCD2U15-03-16KVM2	LCD2U17-03-16KVM2	LCD2U19-02-16KVM2
IP 	2 consoles			LCD2U15-03-16KVM2IP	LCD2U17-03-16KVM2IP	LCD2U19-02-16KVM2IP

PS/2 DB-15 KVM

	1 console	 8 port DB-15 16 port	LCD2U15-03-8KVM	LCD2U17-03-8KVM	LCD2U19-02-8KVM
			LCD2U15-03-16KVM	LCD2U17-03-16KVM	LCD2U19-02-16KVM