

LCD1U17-06-44-L13 1U Rackmount Short Depth LCD Keyboard KVM Drawer



Options



BNC + S-Video



DVI-D



DC Power



Touch Screen



Audio

BNC + S-Video



Touchscreen - USB



DVI-D




Touchscreen - Serial



DC Power



Audio

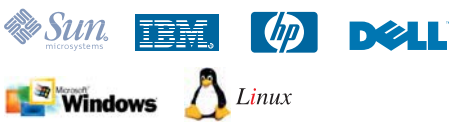

****With touchscreen option, the height of 17-06-44-L13 will be changed from 1U to 1.5U**

Industrial Grade 17" TFT LCD Panel

- 17" 1280 x 1024 LCD with 250 nit brightness and 1000:1 contrast ratio typical

Drawer Features & Options

- 1U rackmount drawer with 17" LCD
- Combo interface either PS/2 or USB input to the LCD drawer
- Multiple keyboard language selections with either touchpad or trackball
- Slide rails with fixed positions to prevent drawer movement when typing
- Enhanced aesthetics with new molded front panel and two point lock

LCD Drawer Benefits

- Short depth design of 440mm (17.3") only
- Depth will suit a 600mm rack application
- "One Man" installation slides for easy, quick installation

 
Dimensions

Model	Product Dimension (W x D x H)	Net Weight
LCD1U17-06-44-L13	442 x 440 x 44 mm 17.4 x 17.3 x 1.73 inch	16 kg / 35 lbs



Diagram

Unit : mm

Left-side View



Front View

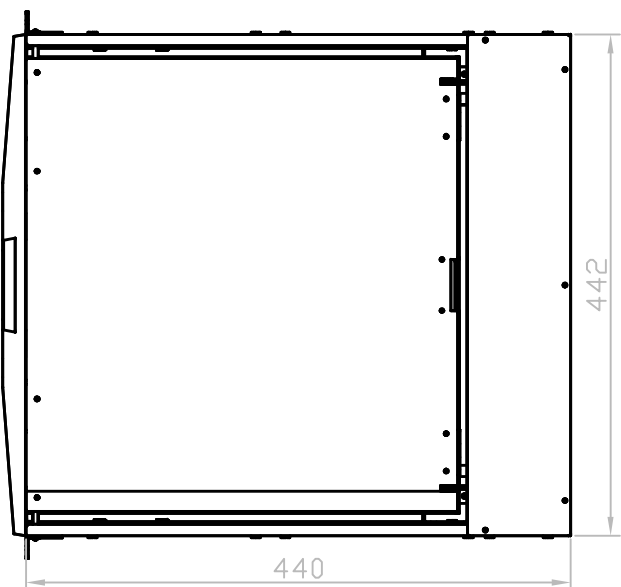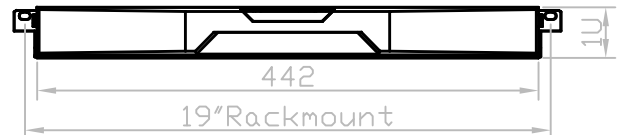

Top View

