

# LCDK1018 1U Rackmount 12-port DVI-D KVM Keyboard Drawer


 



FC CE

## Drawer Features & Benefits

- ▶ Cost effective Combo KVM integration
- ▶ Secure remote user access across the world wide web
- ▶ 104-key keyboard with either trackball (n) or touchpad (b)
- ▶ MAC keyboard options available
- ▶ 12-port DVI-D KVM integration for MAC keyboard option
- ▶ Enhanced aesthetics with molded front handle and two point lock



## Diagrams ( mm )

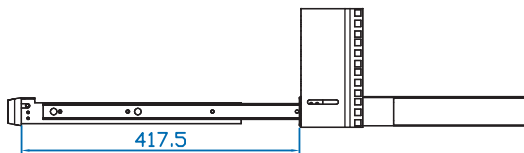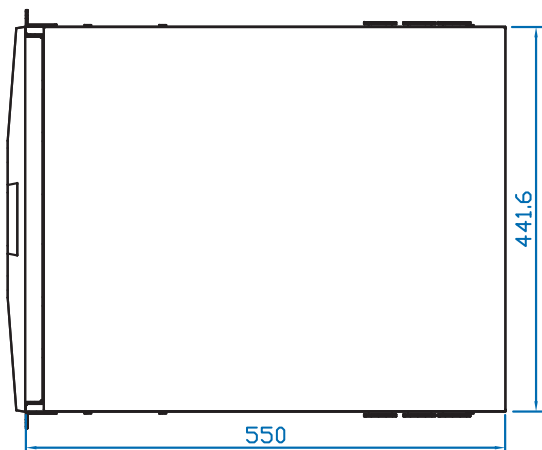


DVI-D KVM Cable : LCD-A3005 / 3006 ( 6 or 15 ft )

## Standard Keyboard

 **Ge** G keyboard integrated with touchpad

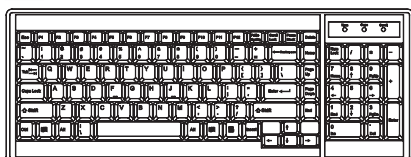

**Gb** G keyboard integrated with trackball

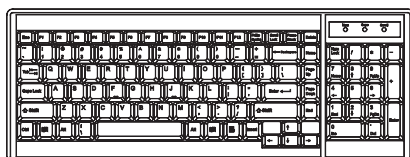

## Supporting layouts

<b>America</b>	United States				
<b>EMEA</b>	United Kingdom	Germany	France	Spain	Norway
	Italy	Russia	Switzerland	Netherlands	Portugal
<b>Asia</b>	China	Japan	Korea	Arabia	Turkey

## Supporting layouts

<b>America</b>	United States
----------------	---------------

## Keyboard Options (Available in n & b version only) \* US layout only

**Me** Mac keyboard with touchpad



**Mb** Mac keyboard with trackball

# LCDK1018 1U Rackmount 12-port DVI-D KVM Keyboard Drawer



- **Dimensions ( with KVM )**



Product : 441.6 x 550 x 44 mm / 17.4 x 21.7 x 1.73 inch

- **Weight**

Net : 11 kgs ( 24 lbs )

- **Casing Color :** Black ( RAL 9005 )

\* For Mac keyboard only

DVI-D KVM	Local	Remote	IP	12-port	-	-
	 	1	0	0	-12DVI	-

DVI-D KVM Cable : LCD-A3005 / 3006 ( 6 or 15 ft )