

ID-32Aw 32" Widescreen Front Aluminum LCD Panel

6mm aluminum front bezel



FC CE

Display Benefits

 
- ▶ 32" widescreen LCD with high resolution 1366 x 768
- ▶ Rugged construction against external impact
- ▶ Standard with HDMI, DVI-D, VGA, S-Video, RCA, Audio & remote controller

Options

- 3G / HD / SD-SDI Broadcast-grade input
- MC Multi-display control solution
- 32" Touchscreen : Capacitive
- Protective toughened glass
- MIL-type or lockable connector
- TV - Analog




Standard I/O



Specifications

• LCD Panel

Manufacturer :	
Size (diagonal) :	32" Widescreen TFT
Max resolution :	1366 x 768
Brightness (cd/m2) :	450
Backlight :	CCFL
Colors :	16.7 M
Contrast ratio (typ) :	5000 : 1
Viewing angle (H/V) :	178° x 178°
Active area (mm) :	698 x 392
MTBF (hrs) :	50,000
Signal input :	HDMI / DVI-D / VGA / S-Video / RCA

• Weight

Net : 23 kgs (50.6 lbs)

• Mounting :

Wall-mount / VESA mount

• Environmental

Operating :	0 to 50°C Degree
Storage :	-5 to 60°C Degree
Relative humidity :	5~90%, non-condensing
Shock :	10G acceleration (11 ms duration)
Vibration :	5~500Hz 1G RMS random vibration

• Casing Color :

Black front panel (RAL 9005)
Dark grey rear case (RAL 7037)

• Regulatory :

FCC, CE

• Power


Input :	Auto-sensing 100 to 240VAC, 50 / 60Hz
Consumption :	Max. 200 Watt, Standby 20 Watt

• Dimensions


Product : 802 x 75 x 496 mm / 31.6 x 3 x 19.5 inch

Diagrams (mm)

Front View

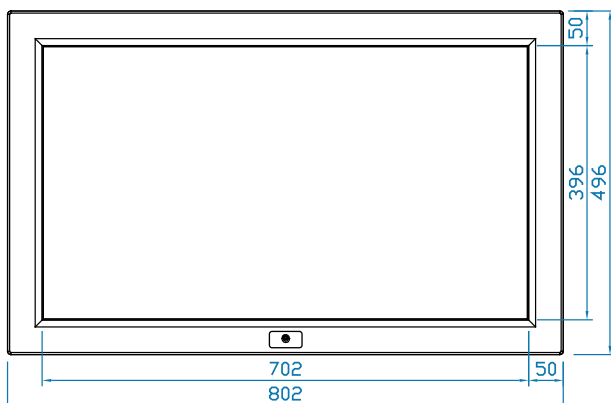

Side View

 

Rear View

