

# LCD1U17-13/ 19-04 1U Rackmount SUN LCD Keyboard/KVM Drawer



## Options



DVI-D



DC Power

### DVI-D




### DC Power



## Dimensions

Model	Product Dimension (W x D x H)	Net Weight
LCD1U17-13	442 x 650 x 44 mm 17.4 x 25.6 x 1.73 inch	15 kg / 33 lbs
LCD1U19-04	442 x 650 x 44 mm 17.4 x 25.6 x 1.73 inch	17 kg / 37 lbs

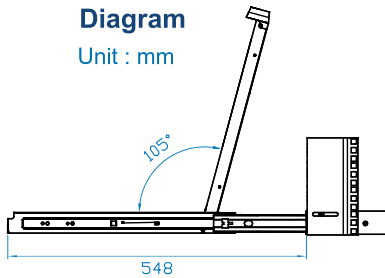

## Drawer Features & Options

- 1U rackmount drawer with either 17" or 19" LCD
- Combo interface either PS/2 or USB input to the LCD drawer
- SUN key support including Stop, Cut, Paste, Compose etc
- US and UK keyboard language selections with either touchpad or trackball
- Slide rails with fixed positions to prevent drawer movement when typing
- Enhanced aesthetics with new molded front panel and two point lock

## LCD Drawer & KVM Benefits

- ▶ Multi-user Matrix KVM with either 16 or 32 ports in 1U
- ▶ Cost efficient Combo KVM integration
- ▶ Direct support for SUN Micro 1152 x 900 native resolution
- ▶ "One Man" installation slides for easy, quick installation
- ▶ Mix PS/2, USB & SUN with Multi-Platform switch capability
- ▶ Secure remote user access across the world wide web


## Monitor Grade A 17" or 19" industrial TFT LCD panel

- 17" 1280 x 1024 LCD with 300 nit brightness and 1000:1 contrast ratio typical
- 19" 1280 x 1024 LCD with 300 nit brightness and 1000:1 contrast ratio typical


## Keyboard Selection

Supporting layouts   USB interface, Incorporates SUN keys

### 104 Keys KB integrated with touchpad

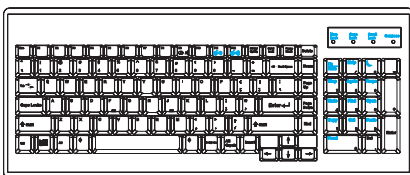

### 104 Keys KB integrated with trackball

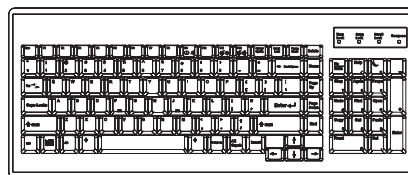













# KVM Selection













Base Model	17" LCD Series	19" LCD Series
<ul style="list-style-type: none"> <li>* Single port w/o KVM</li> <li>* USB interface</li> </ul>	LCD1U17-13	LCD1U19-04












## Matrix Cat6 KVM

	2 consoles	<b>Matrix</b> Cat6 16 port	LCD1U17-13-MU162	LCD1U19-04-MU162
	3 consoles		LCD1U17-13-MU163	LCD1U19-04-MU163
	4 consoles		LCD1U17-13-MU164	LCD1U19-04-MU164
<b>IP</b> 	3 consoles	<b>Matrix IP</b> Cat6 16 port	LCD1U17-13-MU163IP	LCD1U19-04-MU163IP
<b>IP</b> 	4 consoles		LCD1U17-13-MU164IP	LCD1U19-04-MU164IP
<b>IP IP</b> 	4 consoles		LCD1U17-13-MU164IP2	LCD1U19-04-MU164IP2
	2 consoles	<b>Matrix</b> Cat6 32 port	LCD1U17-13-MU322	LCD1U19-04-MU322
	3 consoles		LCD1U17-13-MU323	LCD1U19-04-MU323
	4 consoles		LCD1U17-13-MU324	LCD1U19-04-MU324
<b>IP</b> 	3 consoles	<b>Matrix IP</b> Cat6 32 port	LCD1U17-13-MU323IP	LCD1U19-04-MU323IP
<b>IP</b> 	4 consoles		LCD1U17-13-MU324IP	LCD1U19-04-MU324IP
<b>IP IP</b> 	4 consoles		LCD1U17-13-MU324IP2	LCD1U19-04-MU324IP2







## Matrix DB-15 KVM

	2 consoles	<b>Matrix</b> DB-15 8 port	LCD1U17-13-M82	LCD1U19-04-M82
	3 consoles		LCD1U17-13-M83	LCD1U19-04-M83
	4 consoles		LCD1U17-13-M84	LCD1U19-04-M84
<b>IP</b> 	3 consoles	<b>Matrix IP</b> DB-15 8 port	LCD1U17-13-M83IP	LCD1U19-04-M83IP
<b>IP</b> 	4 consoles		LCD1U17-13-M84IP	LCD1U19-04-M84IP
<b>IP IP</b> 	4 consoles		LCD1U17-13-M84IP2	LCD1U19-04-M84IP2
	2 consoles	<b>Matrix</b> DB-15 16 port	LCD1U17-13-M162	LCD1U19-04-M162
	3 consoles		LCD1U17-13-M163	LCD1U19-04-M163
	4 consoles		LCD1U17-13-M164	LCD1U19-04-M164
<b>IP</b> 	3 consoles	<b>Matrix IP</b> DB-15 16 port	LCD1U17-13-M163IP	LCD1U19-04-M163IP
<b>IP</b> 	4 consoles		LCD1U17-13-M164IP	LCD1U19-04-M164IP
<b>IP IP</b> 	4 consoles		LCD1U17-13-M164IP2	LCD1U19-04-M164IP2

## Combo Cat6 KVM

	1 console	<b>Combo</b> Cat6 8 port	LCD1U17-13-U8KVM	LCD1U19-04-U8KVM
	2 consoles		LCD1U17-13-U8KVM2	LCD1U19-04-U8KVM2
<b>IP</b> 	2 consoles		LCD1U17-13-U8KVM2IP	LCD1U19-04-U8KVM2IP
	1 console	<b>Combo</b> Cat6 16 port	LCD1U17-13-U16KVM	LCD1U19-04-U16KVM
	2 consoles		LCD1U17-13-U16KVM2	LCD1U19-04-U16KVM2
<b>IP</b> 	2 consoles		LCD1U17-13-U16KVM2IP	LCD1U19-04-U16KVM2IP
	1 console	<b>Combo</b> Cat6 32 port	LCD1U17-13-U32KVM	LCD1U19-04-U32KVM
	2 consoles		LCD1U17-13-U32KVM2	LCD1U19-04-U32KVM2
<b>IP</b> 	2 consoles		LCD1U17-13-U32KVM2IP	LCD1U19-04-U32KVM2IP

## Combo DB-15 KVM

	1 console	<b>Combo</b> DB-15 8 port	LCD1U17-13-8KVM-u	LCD1U19-04-8KVM-u
	2 consoles		LCD1U17-13-8KVM2	LCD1U19-04-8KVM2
<b>IP</b> 	2 consoles		LCD1U17-13-8KVM2IP	LCD1U19-04-8KVM2IP
	1 console	<b>Combo</b> DB-15 16 port	LCD1U17-13-16KVM-u	LCD1U19-04-16KVM-u
	2 consoles		LCD1U17-13-16KVM2	LCD1U19-04-16KVM2
<b>IP</b> 	2 consoles		LCD1U17-13-16KVM2IP	LCD1U19-04-16KVM2IP