

LCDR9U20-03 20" Rack Mountable Industrial Monitor




Features

- Support Sun native resolution
- Bright Active Matrix TFT display
- OSD function (On Screen Display) for LCD display
- Panel protected by tempered glass
- Touch screen function (optional)

Specification

Display Size	20.1 inches
Panel Type	Active Matrix TFT LCD
Resolution Capabilities	Maximum Resolution up to 1600 x 1200 (UXGA)
Pixel Pitch	Supports 0.255 mm x 0.255 mm
Viewing Angle (CR>10)	Right-Left view 178° (typical) Up-Down View 178° (typical)
Contrast Ratio	700 : 1
Brightness	White 300 cd/m ²
Back Light	Six Lamps for Back Light
Supported Colors	16.7M Colors (8-bit with FRC)
Response Time	Rising Time 7 ms, Decay Time 9 ms
System Cables	VGA cable / DVI cable
Sync	45 ~ 80 KHz
Power Source	100 ~ 240 VAC input
Temperature	Operate 0 ~ 50 °C / 32 ~ 122 °F Storage -20 ~ 60 °C / -4 ~ 140 °F
Humidity	10% ~ 90% RH
Chassis Construction	Heavy duty steel materials
Touch Panel (optional)	5 wires resistive USB interface / RS232 interface

Dimension

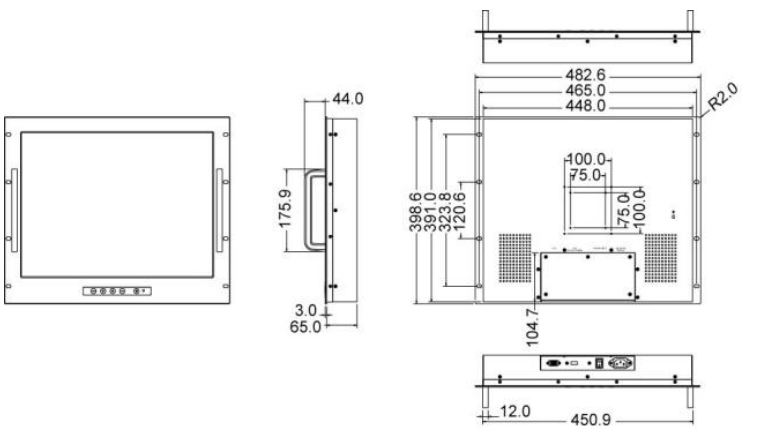

Options

- Color (Black / Beige / OEM color)
- Touch screen (RS232 or USB)
- DVI interface

Contact us about other options and our additional rack mount products.