



Benefits

- ▶ 1U 17" / 19" LCD console drawer
- ▶ 1152 x 900 SUN Micro resolution / 16.7M colors
- ▶ VGA + HDMI video input / USB KB / MS
- ▶ 104-key keyboard with either touchpad or trackball
- ▶ Short depth design of 500mm
- ▶ One Man installation design
- ▶ Enhanced aesthetics with molded front handle and two point lock

Options

- DC power : 12V / 24V / 48V / 110V / 125V / 250V

Product Specifications

Console Port	
Video input	VGA + HDMI
KB / MS	USB interface
HDMI console 6ft cable	Drawer end : HDMI + USB type A x 2 Server end : HDMI + USB type A x 2

LCD Panel	LCD1U17-16	LCD1U19-08
Panel size (diagonal)	17"	19"
Resolution	Direct	1152 x 900
	Native	1280 x 1024
Brightness (cd/m ²)	250	250
Contrast ratio (typ.)	1000 : 1	1000 : 1
Colors	16.7 M	16.7 M
Viewing angle (L/R/U/D)	85/85/80/80	85/85/80/80
Response time (ms)	5	5
Dot pitch (mm)	0.264	0.294
Display area (mm)	337.92H x 270.33V	376.32H x 270.33V
Surface treatment	Haze 25%, Hard-coating	
Surface hardness	3H	
Backlight type	LED	
MTBF (hrs)	30,000	

Physical	LCD1U17-16	LCD1U19-08
Product (W x D x H)	Single console	442 x 500 x 44 mm 17.4 x 19.7 x 1.73 inch
	Console w/ KVM	442 x 620 x 44 mm 17.4 x 24.4 x 1.73 inch
Net weight	Single console	12.3 kg / 27.1 lb
	Console w/ KVM	13.3 kg / 29.2 lb

* All dimensions stated are subject to change if options are selected / integrated to base model part codes

Mounting Distance	LCD1U17-16	LCD1U19-08
Single console drawer	510 ~ 740 mm 20.1 ~ 29.1 inch	510 ~ 740 mm 20.1 ~ 29.1 inch
Console w/ KVM drawer	510 ~ 840 mm 20.1 ~ 33.1 inch	510 ~ 840 mm 20.1 ~ 33.1 inch

Audio Option		
Input	Connector	3.5mm stereo jack
	Impedance / Power level	30kΩ / 750mV
Output	Connector	3.5mm stereo jack
	Resistance / Power level	30kΩ / 2.8V
Speaker	Dual stereo	2W x 2

Power		
Input	Auto-sensing 100 to 240VAC, 50 / 60Hz	
Consumption (console / KVM)	Screen on	Max. 22W / Max. 55W
	Power saving mode	Max. 2W / Max. 34W
	Power button off	Max. 1W / Nil

Environment	
Operating temp.	0 to 55°C degree
Storage temp.	-20 to 60°C degree
Operating humidity	10~90%, non-condensing
Storage humidity	5 ~90%, non-condensing
Operating altitude	16,000 ft
Non-operating altitude	40,000 ft
Shock	10G acceleration (11ms duration)
Vibration	10~300Hz 0.5G RMS random vibration

Compliance	
EMC	FCC & CE
Safety	CE / LVD & UKCA
Environment	REACH & RoHS3 / WEEE

2K KVM	IP	Remote	8-port
	0	0	-8HD

2K KVM Cable




Resolution 16:9 - max. 2560 x 1440
 Support **: 16:10 - max. 1920 x 1200
 4:3 - max. 1600 x 1200
**** Resolution related to LCD specification**

LCD-A3011 (6 ft) DVI-D KVM cable LCD-A3012 (6 ft) HDMI KVM cable

DVI-D KVM	IP	Remote	12-port
	0	0	-12DVI

DVI-D USB KVM Cable

Resolution 16:10 - max. 1920 x 1200
 Support **: 16:9 - max. 1920 x 1080
 4:3 - max. 1600 x 1200



LCD-A3005 (6 ft)
 LCD-A3006 (15 ft)

Cat6 Matrix KVM	IP	Remote	8-port	16-port	32-port
	1	1	-	-MU164IP2	-MU324IP2
	2	1	-	-MU163IP	-MU323IP
	0	1	-	-MU162	-MU322
	0	2	-	-MU163	-MU323
	0	3	-	-MU164	-MU324

Cat6 KVM Dongle




LCD-A2005 DP - USB dongle LCD-A2004 HDMI - USB dongle LCD-A2003 DVI - USB dongle
 LCD-A2001 VGA - USB dongle LCD-A2002 VGA - PS/2 dongle

Resolution 16:10 - max. 1920 x 1200
 Support **: 16:9 - max. 1920 x 1080
 4:3 - max. 1600 x 1200
**** Resolution related to LCD specification**

Cat6 Combo KVM	IP	Remote	8-port	16-port	32-port
	1	0	-U8KVM2IP	-U16KVM2IP	-U32KVM2IP
	0	1	-U8KVM2	-U16KVM2	-U32KVM2
	0	0	-U8KVM	-U16KVM	-U32KVM

DB-15 Combo KVM	IP	Remote	8-port	16-port
	1	0	-8KVM2IP	-16KVM2IP
	0	0	-8KVM	-16KVM


DB-15 VGA USB KVM Cable



LCD-A1014(6 ft) LCD-A1015 (10 ft) LCD-A1016 (15 ft)

Resolution 16:10 - max. 1920 x 1200
 Support : 16:9 - max. 1920 x 1080
 4:3 - max. 1600 x 1200
**** Resolution related to LCD specification**

IP Console

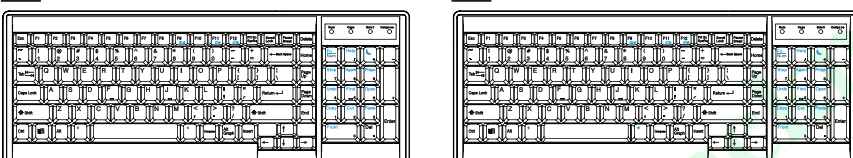



High Performance KVM Access Over IP

Connector : RJ45
 User management : 1 x active user, 15-user login
 Network protocol : DHCP / BOOTP / DNS
 Security : TLS 1.3, AES, LDAP, Active Directory (AD), HTTP(s)
 Browser : Chrome, Firefox, Edge, etc.
 Resolution : 16:9 - max. 1920 x 1080 / 16:10 - max. 1920 x 1200 / 4:3 - max. 1600 x 1200

Keyboard

Sn SUN keyboard with touchpad **Sb** SUN keyboard with trackball

Supporting layouts

America  U.S.