

Features


- Meet MIL-STD-810F/G standard
- 1U 17.3" LCD Console Drawer
- support 1920 x 1080 FHD resolution
- DVI & VGA Port
- Front 1x USB, Rear 1 x USB 2.0 Type A, Sharing USB peripheral Device for computer (ex, flash disk, hard driver, KB/Mouse)
- Sealed IP65 silicone keyboard and trackball with backlight
- MIL connector for power input
- Support USB 2.0 Keyboard & Mouse
- Self-locking and auto release rails for ultra convenience

Options

- HDMI, Display port input
- DC 9~36V power input
- High brightness LCD panel, up to 1000 nits
- Resistive touchscreen



(USB Port for device access)

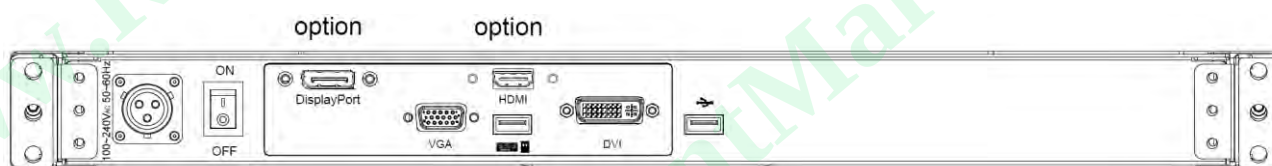

Rear of MIL1U17-03

Part No.		MIL1U17-03
Direct no. of Computers		1
LCD	Size	17.3"
	Backlight	LED
	Resolution	1920*1080 Full HD (support resolution up to 1920x1200)
	Max.color	16.7M
	Luminance	400cd/m2
	View Angel (H/V)	160 / 140
	Contrast Ratio	600 : 1
USB HUB		1x Front , 1xRear USB 2.0 Type A for Peripheral USB Device
KB/Mouse Emulation		USB
Rack Depth		With Short mounting bracket: 380mm to 620mm (rack cabinet front rails to rear rails) With Long mounting bracket: 560mm to 762mm (rack cabinet front rails to rear rails)
Power		100-240V AC 50/60Hz via 3 pins lock connector
Environment (MIL-STD-810G)	Operation temp: 0 to 50°C	(MIL-STD-810, Method 501.5 & 502.5)
	Storage temp: -20 to 60°C	(MIL-STD-810, Method 501.5 & 502.5)
	Humidity: 5% - 95%, non-condensing	(MIL-STD-810, Method 507.5)
	Shock/Vibration: Procedure VI, 50G @ 11ms	(MIL-STD-810, Method 516.6)
	Altitude: 10,000 ft Operational, 30,000 ft Storage	(MIL-STD-810, Method 500.5)
Physical Dimensions / Net Weights		482x44x408mm (WxHxD) /13KG