



Benefits

- ▶ 2U 17" / 19" LCD console drawer
- ▶ Dual slide - LCD and keyboard slide independently
- ▶ 1152 x 900 SUN Micro resolution / 16.7M colors
- ▶ 104-key keyboard with either touchpad or trackball
- ▶ Short depth design of 480mm
- ▶ One Man installation design
- ▶ Enhanced aesthetics with molded front handle and two point lock

Options

- DC power : 12V / 24V / 48V / 110V / 125V

Product Specifications

Console Port	
Video input	VGA
KB / MS	USB interface
VGA console 6ft cable	Drawer end : DB-15 + USB type A x 2 Server end : DB-15 + USB type A x 2

LCD Panel	LCD2U17-04	LCD2U19-03
Panel size (diagonal)	17"	19"
Resolution	Direct	1152 x 900
	Native	1280 x 1024
Brightness (cd/m ²)	250	250
Contrast ratio (typ.)	1000 : 1	1000 : 1
Colors	16.7 M	16.7 M
Viewing angle (L/R/U/D)	85/85/80/80	85/85/80/80
Response time (ms)	5	5
Dot pitch (mm)	0.264	0.294
Display area (mm)	337.92H x 270.33V	376.32H x 270.33V
Surface treatment	Haze 25%, Hard-coating	
Surface hardness	3H	
Backlight type	LED	
MTBF (hrs)	30,000	

Audio Option		
Input	Connector	3.5mm stereo jack
	Impedance / Power level	30kΩ / 750mV
Output	Connector	3.5mm stereo jack
	Resistance / Power level	30kΩ / 2.8V
Speaker	Dual stereo	2W x 2

Power		
Input	Auto-sensing 100 to 240VAC, 50 / 60Hz	
	Screen on	Max. 25W / Max. 55W
	Power saving mode	Max. 4W / Max. 34W
	Power button off	Max. 1W / Nil

Physical		LCD2U17-04	LCD2U19-03
Product (W x D x H)	Single console	442 x 480 x 88 mm 17.4 x 18.9 x 3.5 inch	442 x 480 x 88 mm 17.4 x 18.9 x 3.5 inch
	Console w/ KVM	442 x 480 x 88 mm 17.4 x 18.9 x 3.5 inch	442 x 480 x 88 mm 17.4 x 18.9 x 3.5 inch
Net weight	Single console	20.4 kg / 44.9 lb	20.5 kg / 45.1 lb
	Console w/ KVM	21.1 kg / 46.4 lb	21.5 kg / 47.3 lb

* All dimensions stated are subject to change if options are selected / integrated to base model part codes

Environment	
Operating temp.	0 to 55°C degree
Storage temp.	-20 to 60°C degree
Operating humidity	20~90%, non-condensing
Storage humidity	5 ~90%, non-condensing
Operating altitude	16,000 ft
Non-operating altitude	40,000 ft
Shock	10G acceleration (11ms duration)
Vibration	10~300Hz 0.5G RMS random vibration

Mounting Distance	LCD2U17-04	LCD2U19-03
Single console drawer / Console w/ KVM drawer	490 ~ 700 mm 19.3 ~ 27.6 inch	490 ~ 700 mm 19.3 ~ 27.6 inch

Compliance	
EMC	FCC & CE certified
Safety	CE / LVD certified
Environment	RoHS2 & REACH compliant

** Resolution related to LCD specification

2K KVM	IP	Remote	8-port
	0	0	-8HD

2K KVM Cable



LCD-A3011 (6 ft)
DVI-D KVM cable



LCD-A3012 (6 ft)
HDMI KVM cable

Resolution 16:9 - max. 2560 x 1440
Support **: 16:10 - max. 1920 x 1200
4:3 - max. 1600 x 1200

DVI-D KVM	IP	Remote	12-port
	0	0	-12DVI

DVI-D USB KVM Cable


Resolution 16:10 - max. 1920 x 1200
Support **: 16:9 - max. 1920 x 1080
4:3 - max. 1600 x 1200




LCD-A3005 (6 ft)
LCD-A3006 (15 ft)

Cat6 Matrix KVM	IP	Remote	8-port	16-port	32-port
	1	1	-	-MU164IP2	-MU324IP2
	2	1	-	-MU163IP	-MU323IP
	0	1	-	-MU162	-MU322
	0	2	-	-MU163	-MU323
	0	3	-	-MU164	-MU324


Cat6 KVM Dongle




LCD-A2005
DP - USB dongle




LCD-A2004
HDMI - USB dongle



LCD-A2003
DVI - USB dongle



LCD-A2001
VGA - USB dongle



LCD-A2002
VGA - PS/2 dongle


Resolution 16:10 - max. 1920 x 1200
Support **: 16:9 - max. 1920 x 1080
4:3 - max. 1600 x 1200

Cat6 Combo KVM	IP	Remote	8-port	16-port	32-port
	1	0	-U8KVM2IP	-U16KVM2IP	-U32KVM2IP
	0	1	-U8KVM2	-U16KVM2	-U32KVM2
	0	0	-U8KVM	-U16KVM	-U32KVM


** Resolution related to LCD specification

DB-15 Matrix KVM	IP	Remote	8-port	16-port
	1	1	-M83IP	-M163IP
	2	1	-M84IP2	-M164IP2
	0	1	-M82	-M162
	0	2	-M83	-M163
	0	3	-M84	-M164


DB-15 VGA USB KVM Cable



LCD-A1014 (6 ft)



LCD-A1015 (10 ft)



LCD-A1016 (15 ft)



Resolution 16:10 - max. 1920 x 1200
Support : 16:9 - max. 1920 x 1080
4:3 - max. 1600 x 1200

** Resolution related to LCD specification


DB-15 Combo KVM	IP	Remote	8-port	16-port
	1	0	-8KVM2IP	-16KVM2IP
	0	1	-8KVM2	-16KVM2
	0	0	-8KVM-u	-16KVM-u

Keyboard

 Sn SUN keyboard integrated with touchpad

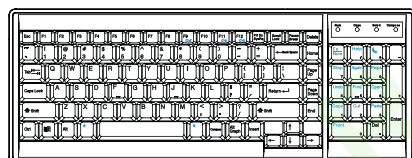

Sb SUN keyboard integrated with trackball

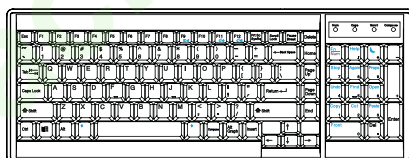

Supporting layouts

America 
United States