


ID-08P-LED 8.4" LCD with LED-backlit Display

Universal open frame mounting

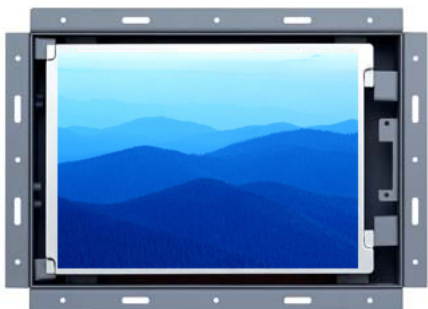

 
FC CE

Display Benefits

- ▶ 8.4" LCD with resolution 800 x 600
- ▶ Green LED-backlit panel technology
- ▶ Rugged construction against external impact

Options

- S-Video + BNC & Audio
- 8.4" Touchscreen : Capacitive, Resistive
- 48V, 24V or 12VDC power
- TV - PAL or NTSC



Standard I/O : VGA only

Options I/O : S-Video + BNC, Audio, TV, USB for touchscreen

Specifications

• LCD Panel

Manufacturer :	AUO
Size (diagonal) :	8.4" TFT
Max resolution :	800 x 600
Brightness (cd/m2) :	250
Backlight :	LED
Colors :	262 K
Contrast ratio (typ) :	600 : 1
Viewing angle (H/V) :	160° x 140°
Active area (mm) :	170 x 128
MTBF (hrs) :	30,000
Signal input :	VGA

• Weight

Net : 2 kgs (4.4 lbs)

• Mounting : Universal mount / VESA mount

• Environmental

Operating :	0 to 50°C Degree
Storage :	-5 to 60°C Degree
Relative humidity :	5~90%, non-condensing
Shock :	10G acceleration (11 ms duration)
Vibration :	5~500Hz 1G RMS random vibration

• Casing Color :

Dark grey (RAL 7037)

• Regulatory :

FCC, CE

• Power

Input :	Auto-sensing 100 to 240VAC, 50 / 60Hz
Consumption :	Max. 40 Watt, Standby 5 Watt

• Dimensions

Product : 262 x 57 x 189 mm / 10.3 x 2.2 x 7.4 inch

Diagrams (mm)

Front View

Side View

Rear View

