

ID-32Aw 32" Widescreen Front Aluminum LCD Panel

6mm aluminum front bezel




Display Benefits

- ▶ 32" widescreen LCD with high resolution 1366 x 768
- ▶ Rugged construction against external impact
- ▶ Standard with HDMI, VGA, S-Video, RCA, Audio & remote controller

Options

- Protective toughened glass
- TV - Analog

Basic I/O

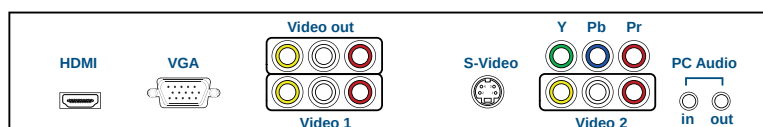

Specifications

• LCD Panel

Manufacturer :	
Size (diagonal) :	32" Widescreen TFT
Max resolution :	1366 x 768
Brightness (cd/m2) :	450
Backlight :	CCFL
Colors :	16.7 M
Contrast ratio (typ) :	5000 : 1
Viewing angle (H/V) :	178° x 178°
Active area (mm) :	698 x 392
MTBF (hrs) :	50,000
Signal input :	HDMI / VGA / S-Video / RCA

• Weight

Net :	23 kgs (50.6 lbs)
-------	---------------------

• Mounting :

Wall-mount / VESA mount

• Environmental

Operating :	0 to 50°C Degree
Storage :	-5 to 60°C Degree
Relative humidity :	5~90%, non-condensing
Shock :	10G acceleration (11 ms duration)
Vibration :	5~500Hz 1G RMS random vibration

• Casing Color :

Black (RAL 9005)

• Regulatory

Safety :	FCC & CE certified
Environmental	RoHS2 & REACH compliant

• Power


Input :	Auto-sensing 100 to 240VAC, 50 / 60Hz
Consumption :	Max. 200 Watt, Standby 20 Watt

• Dimensions


Product :	850 x 135.3 x 520 mm / 33.5 x 5.3 x 20.5 inch
-----------	---

Diagrams (mm)

Front View

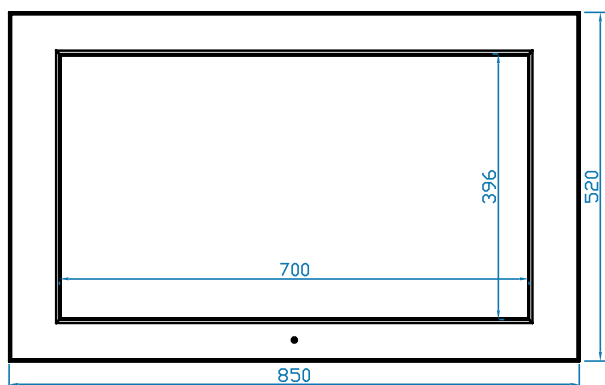

Side View

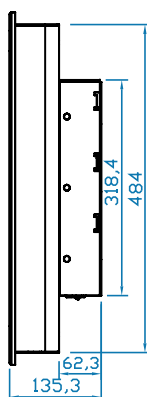

Rear View

