

ID-46Aw-LED 46" High Resolution Widescreen LCD Panel w/ LED-backlit Display



6mm aluminum front bezel with optional

NEMA 4 / IP65
front protection

 


Display Benefits

- ▶ 46" widescreen LCD with **Full HD** 1080p resolution
- ▶ Green LED-backlit panel technology
- ▶ Rugged construction against external impact
- ▶ Standard with HDMI, DVI-D, VGA, S-Video, RCA, Audio & remote controller

Options

- 3G / HD / SD-**SDI** Broadcast-grade input
- **MCS** Multi-display control solution
- NEMA4 / IP65 front Protective toughened glass
- MIL-type or lockable connector
- TV - PAL or NTSC



Standard I/O : HDMI, DVI-D, Audio, S-Video, RCA, VGA

Options I/O : TV
SDI or MC (either one)

Specifications

• LCD Panel

Manufacturer :	
Size (diagonal) :	46" TFT
Max resolution :	1920 x 1080
Brightness (cd/m2) :	400
Backlight :	LED
Colors :	16.7 M
Contrast ratio (typ) :	4000 : 1
Viewing angle (H/V) :	178° x 178°
Active area (mm) :	1018 x 573
MTBF (hrs) :	30,000
Signal input :	HDMI / DVI-D / VGA / S-Video / RCA

• Weight

Net :	50 kgs (110 lbs)
-------	--------------------

• Mounting :

Wall-mount

• Environmental

Operating :	0 to 50°C Degree
Storage :	-5 to 60°C Degree
Relative humidity :	5~90%, non-condensing
Shock :	10G acceleration (11 ms duration)
Vibration :	5~500Hz 1G RMS random vibration

• Casing Color :

Black front panel (RAL 9005)
Dark grey rear case (RAL 7037)

• Regulatory :

FCC, CE

• Power


Input :	Auto-sensing 100 to 240VAC, 50 / 60Hz
Consumption :	Max. 200 Watt, Standby 20 Watt

• Dimensions


Product :	1121 x 82 x 676 mm / 44 x 3.2 x 26.6 inch
-----------	---

Diagrams (mm)

Front View

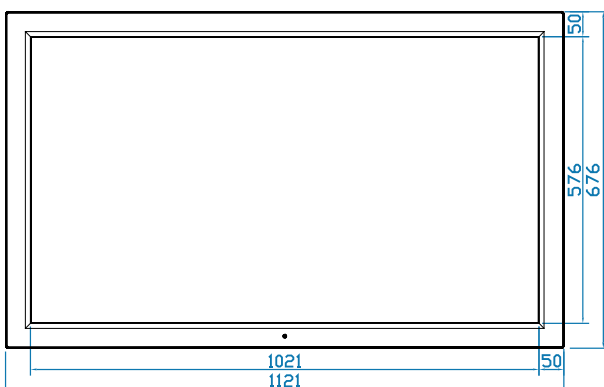

Side View

 

Rear View

