


LCD1U19-016 1U 19" Rackmount Quad LCD Display

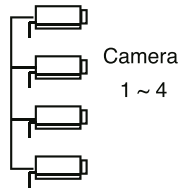

Drawer Features & Display Benefits


- ▶ 1U 19" LCD drawer
- ▶ Built-in Quad Display
- ▶ Ideal for CCTV security & industrial control
- ▶ Sliding LCD allowing LCD to remain open when the rack door is closed

Option ● DC power : 12V / 24V / 48V / 110 ~ 125V

Front QD membrane button



Rear I/O

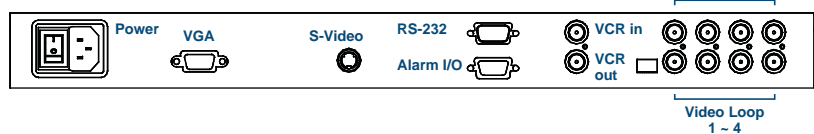

Specifications

• LCD Panel

Manufacturer :	AUO
Size (diagonal) :	19" TFT
Max resolution :	1280 x 1024
Brightness (cd/m ²) :	250
Backlight :	LED
Colors :	16.7 M
Contrast ratio (typ) :	1000 : 1
Viewing angle (H/V) :	170° x 160°
Active area (mm) :	376 x 301
MTBF (hrs) :	30,000
Signal input :	VGA

• **Power Input :** Auto-sensing 100 to 240VAC, 50 / 60Hz

• Power Consumption

Screen on :	Max. 25W
Power saving mode :	Max. 4W
Power button on :	Max. 1W

• Environmental

Operating temperature :	0 to 55°C degree
Storage temperature :	-20 to 60°C degree
Operating humidity :	20~90%, non-condensing
Storage humidity :	5 ~90%, non-condensing
Operating altitude :	16,000 ft
Non-operating altitude :	40,000 ft
Shock :	10G acceleration (11ms duration)
Vibration :	5~500Hz 1G RMS random vibration

• **Casing Color :** Black (RAL 9005)

• Regulatory

Safety :	FCC & CE certified
Environmental :	RoHS2 & REACH compliant

• Weight

Net :	12.5 kgs / 27.5 lbs
-------	---------------------

• Dimensions

Product :	442 x 650 x 44 mm / 17.4 x 25.6 x 1.73 inch
-----------	---

Diagrams (mm)

