




Features

- 2U dual vertical 19 inch LCD Console Drawer
- 2 gas struts to support LCD when open
- Dual DVI & VGA Port
- 1280 x 1024 resolution
- Dual rail design, capable the LCD screen and keyboard tray Operated independently.
- Front 1xUSB, Rear 2xUSB 2.0 Type A, Sharing USB peripheral Device for computer (ex, flash disk, hard driver, KB/Mouse)
- 104-key keyboard with touch pad mouse.
- USB 2.0 Keyboard & Mouse
- Build in 2x 2 watts speakers

Options

- Composite Video input
- HDMI or Display Port input
- 3G / HD / SD –SDI Broadcast grade input
- 48V, 24V or 12V DC Power

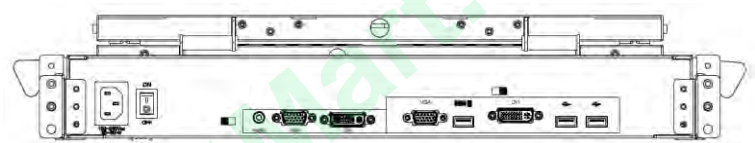

Rear of LCD2U19-2T-01

Part No.	LCD2U19-2T-01	
No. of ports	1	
KVM Connectors	2 x DVI-D & 2x VGA / 1 x USB for KB & Mouse / 1x Audio	
LCD	Size	Dual 19 inch
	Backlight	LED
	Resolution	1280*1024
	Max.color	16.7M
	Luminance	250 cd/m2
	View Angel (H/V)	170 / 170
	Contrast Ratio	1000 : 1
Port Selection	N/A	
USB HUB	Yes , Front x1 & Rear x 2 USB 2.0 Type A for USB Peripheral Device	
Audio	1 x 3.5mm Audio jack	
KB/Mouse Emulation	USB 2.0	
Rack Depth ( rack cabinet front rails to rear rails )	610mm to 940mm	
Power	100-240V AC 50/60Hz via IEC Type power cord	
Environment	Operation temp: 0 to 50°C	
	Storage temp: -20 to 60°C	
	Humidity: 10% - 90%, non-condensing	
	Shock: 10G acceleration ( 11ms duration) Vibration: 17 to 500Hz 1G PTP	
Physical Dimensions ( W x H x D ) / Net Weights ( KGs )	443x87x609mm / 21.0	