

Features


- 2U Dual 23.8-inch widescreen LCD Console Drawer
- Dual DVI & VGA Port
- 1920 x 1080 high resolution
- Support FHD with 1080p resolution.
- Dual rail design, capable the LCD screen and keyboard tray Operated independently.
- Front 1xUSB, Rear 2xUSB 2.0 Type A, Sharing USB peripheral Device for computer (ex, flash disk, hard driver, KB/Mouse)
- 104-key keyboard with touch pad mouse.
- USB 2.0 Keyboard & Mouse
- Build in 2x 2 watts speakers

Options

- Composite Video input
- HDMI or Display Port input
- 48V, 24V or 12V DC Power
- AR glass
- Touch screen



(USB Port for device access)

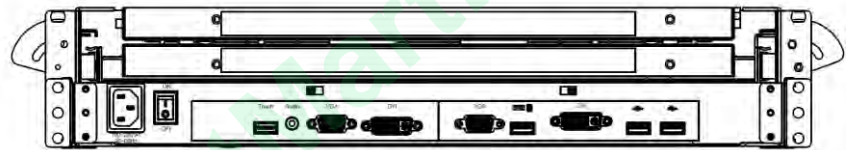

Rear of LCD2U24-2H-01

| Part No. | | LCD2U24-2H-01 |
|---|------------------|--|
| No. of ports | | 1 |
| KVM Connectors | | 2 x DVI-D & 2x VGA / 1 x USB for KB & Mouse / 1x Audio |
| LCD | Size | Dual 23.8-inch FULL HD display |
| | Backlight | LED |
| | Resolution | 1920*1080 (support resolution up to 1920*1200) |
| | Max.color | 16.7M |
| | Luminance | 350 cd/m2 |
| | View Angel (H/V) | 170 / 160 |
| | Contrast Ratio | 1000 : 1 |
| Port Selection | | N/A |
| USB HUB | | Yes , Front x1 & Rear x 2 USB 2.0 Type A for USB Peripheral Device |
| Audio | | 1 x 3.5mm Audio jack |
| KB/Mouse Emulation | | USB 2.0 |
| Rack Depth (rack cabinet front rails to rear rails) | | 24"~43" (rack cabinet front rails to rear rails) |
| Power | | 100-240V AC 50/60Hz via IEC Type power cord |
| Environment | | Operation temp: 0 to 50°C Storage temp: -20 to 60°C Humidity: 10% - 90%, non-condensing Shock: 10G acceleration (11ms duration) Vibration: 17 to 500Hz 1G PTP |
| Physical Dimensions (W x H x D) / Net Weights (KGs) | | 443 x 88 x 762 mm/ 32KG |