

# RM4035 4U 19" RACKMOUNT CHASSIS WITH FRONT ACCESSIBLE USB PORT



## Feature


- 4U rackmount chassis meet EIA-310C
- Max support seven 3.5" Disk Drives
- Two front accessible USB ports

## Specification


- 4U Rackmount chassis meet EIA-310C
- Construction: high strength 1.2mm SGCC structural steel
- Color: Black
- System Boards: Dual Xeon, Pentium 4, Dual Pentium III based boards
- Board Size: Support ATX M/B (Max. 12" x 9.6")
- Drive Bays: 2x5.25" + 1x3.5"FDD open + 7x3.5"HDD hidden.
- Power Supply: PS2(optional)
- Cooling Units: 1x12cm Fan (Front) and 2x8cm Fans (Rear)
- Expansion Slot: 7-Slot
- Indicators: LED for Power & HDD Activity & keyboard locker
- Buttons: Power On/Off, Alarm & System Reset
- I/O Port: Two front accessible USB ports
- Dimensions: 480(W) x 177(H) x 500(D) mm (19" x 7" x 19.7")
- Weight: 14 kg/30.8 lbs
- Cft.: 3.0
- Carton Size: 630x 520x 260 (mm) (24.8" x 20.5" x 10.2")
- Product Application: Web Server, Firewall Server, Proxy Server, VPN Gateway, High-End Workstation

## Structure


### InsideView

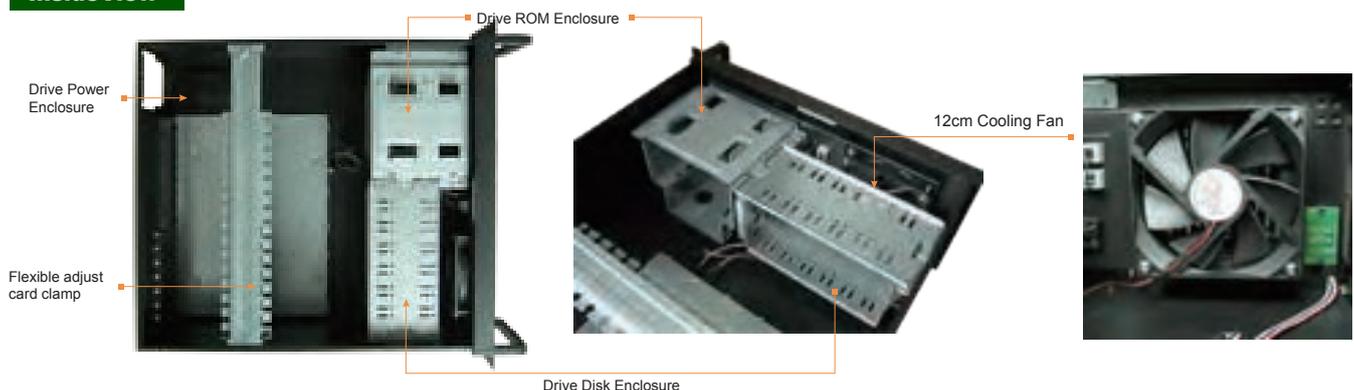


**Front Panel**

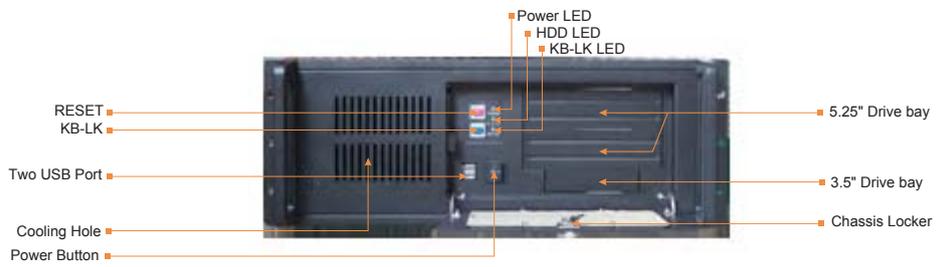

**ATX Back Window**

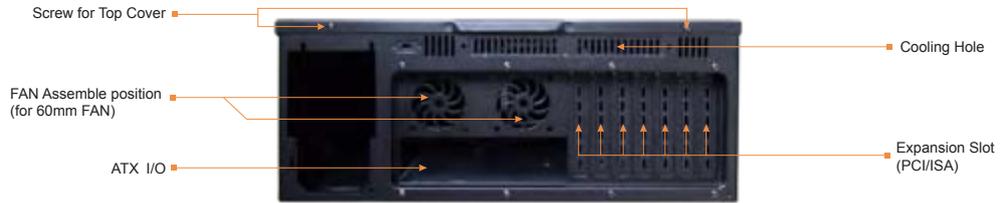


**System Cooling**

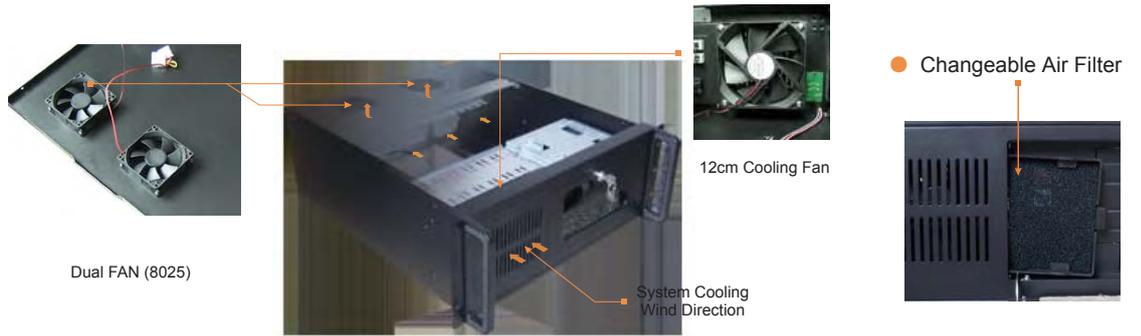


**Dimensions**


Front 1:

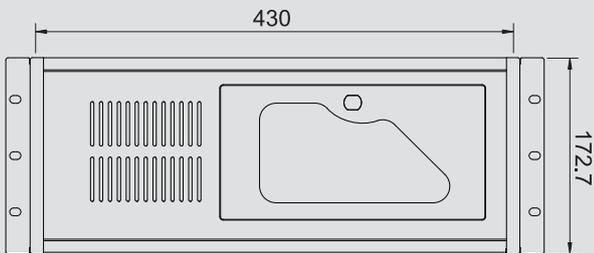


Front 2:

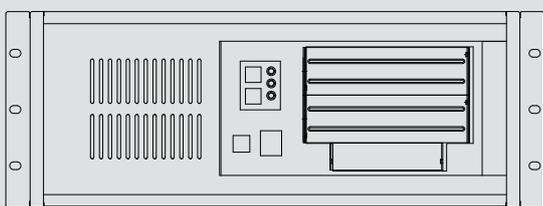

Rear:

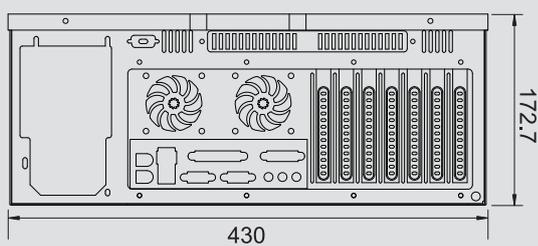

Top:

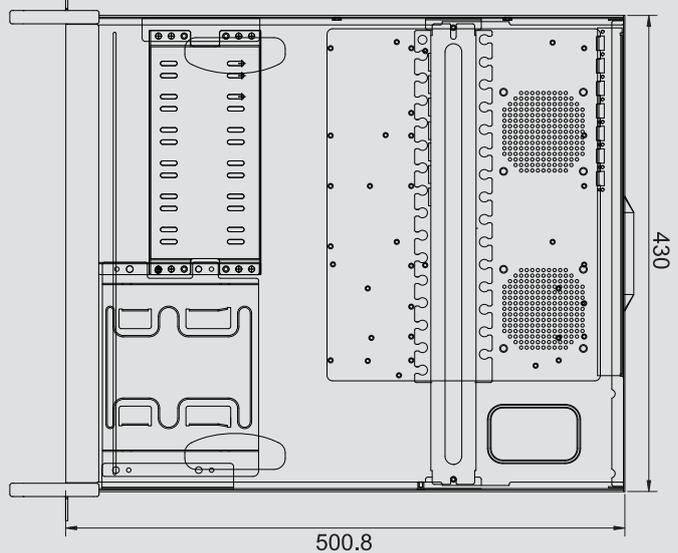

Side:

