


## Rack PDU

### Overview

**Outlets.** The PDU has fifteen (15) IEC-320-C13 outlets.

**Power cord.** The 6.5-foot (1.98-meter) power cord terminates with a IEC-320-C14 plug.

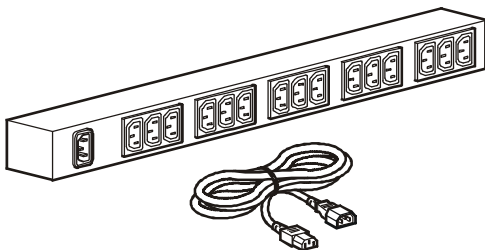

**RA5015-C13-10A-C14**

# Specifications

---

## Electrical

---

Input connector	IEC-320-C14 inlet
Output connectors	(15) IEC-320-C13 outlets
Nominal input voltage	120-240 VAC
Acceptable input voltage	± 10% of nominal voltage
Input frequency	50/60 Hz

---

## Physical

---

Dimensions (H × W × D)	24.00 × 1.75 × 1.75 in (60.96 × 4.44 × 4.44 cm)
Shipping dimensions (H × W × D)	25.13 × 6.63 × 5.75 in (63.81 × 16.82 × 14.60 cm)
Weight	4.40lb (2.19kg)

---

## Environmental

---

Elevation (above MSL)	
Operating	0 – 10,000 ft (0 – 3000m)
Storage	0 – 50,000 ft (0 – 15 000m)
Temperature	
Operating	32 to 113° F (0 to 45° C)
Storage	-13 to 149° F (-25 to 65° C)
Humidity	
Operating	5 – 95% RH non-condensing
Storage	5 – 95% RH non-condensing

---

## Compliance

---

Safety	UL/ cUL Listed UL 60950, EN 60950, VDE, AS/NZS 60950
--------	--

---



**Synergy Global Technology Inc**

[www.RackmountMart.com](http://www.RackmountMart.com)