




**Synergy Global Technology Inc**

*www.RackmountMart.com*

## Basic Rack PDU

**Outlets.** The PDU has fifteen (15) IEC-320-C13 outlets.

**Power cord.** 2.5-m (8.2-ft) IEC-320-C19 to IEC-320-C20 power cord.

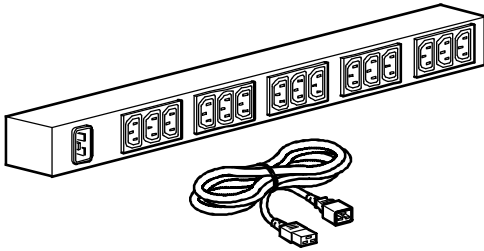

**RA5015-C13-16A-C20**

## Specifications

### Electrical

Input connector	IEC-320-C20 plug
Output connectors	fifteen (15) IEC-320-C13 outlets
Nominal input voltage	120 – 230 VAC
Acceptable input voltage	120 – 240 VAC +6%, -10%
Input frequency	50/60 Hz

### Physical

Dimensions (H × W × D)	62.00 × 4.44 × 4.44 cm (24.40 × 1.75 × 1.75 in)
Shipping dimensions (H × W × D)	63.81 × 16.82 × 14.60 cm (25.13 × 6.63 × 5.75 in)
Weight	2.00 kg (4.40 lb)

### Environmental

Elevation (above MSL)	
Operating	0 – 3000 m (0 – 10,000 ft)
Storage	0 – 15 000 m (0 – 50,000 ft)
Temperature	
Operating	0 to 45° C (32 to 113° F)
Storage	-25 to 65° C (-13 to 149° F)
Humidity	
Operating	5 – 95% RH, non-condensing
Storage	5 – 95% RH, non-condensing

### Compliance

Safety verifications	UL/cUL Listed, CE, VDE, AS/NZS 60950-1
----------------------	---



**Synergy Global Technology Inc**

[www.RackmountMart.com](http://www.RackmountMart.com)