


Overview

Outlets. The Rack PDU has twenty-four NEMA 5-20 outlets.

Power cord. The 10-foot (3.05-meter) power cord terminates with a NEMA L5-30 connector.

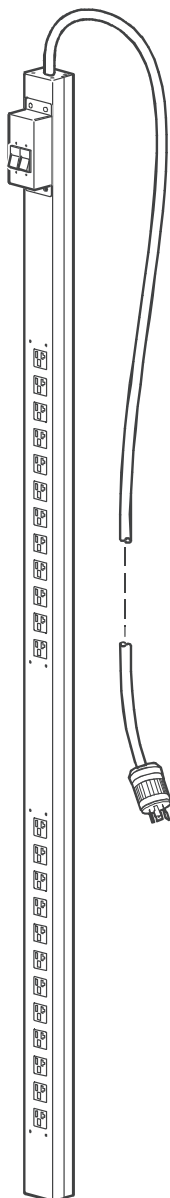

Specifications

Electrical

Input connector	NEMA L5-30 plug
Output connectors	24–NEMA 5-20 outlets
Nominal input voltage	120 VAC
Acceptable input voltage	± 10% of normal voltage
Input frequency	50/60 Hz

Physical

Size (H × W × D)	63.75 x 2.19 x 1.73 in (161.92 x 5.56 x 4.39 cm)
Shipping Dimensions (H × W × D)	84.00 x 6.00 x 5.00 in (213.36 x 15.24 x 12.7 cm)
Weight	12.25 lb (5.56 kg)

Environmental

Elevation (above MSL)	
Operating	0–15,000 ft (0–4500 m)
Storage	0–50,000 ft (0–15 000 m)
Temperature	
Operating	23 to 115° F (–5 to 45° C)
Storage	–13 to 149° F (–25 to 65° C)
Humidity	
Operating	5–95% RH non-condensing
Storage	5–95% RH non-condensing

Compliance

Safety verification	UL, cUL 60950
---------------------	---------------
