


# LCDR6U15-01 LCD Rackmount Display

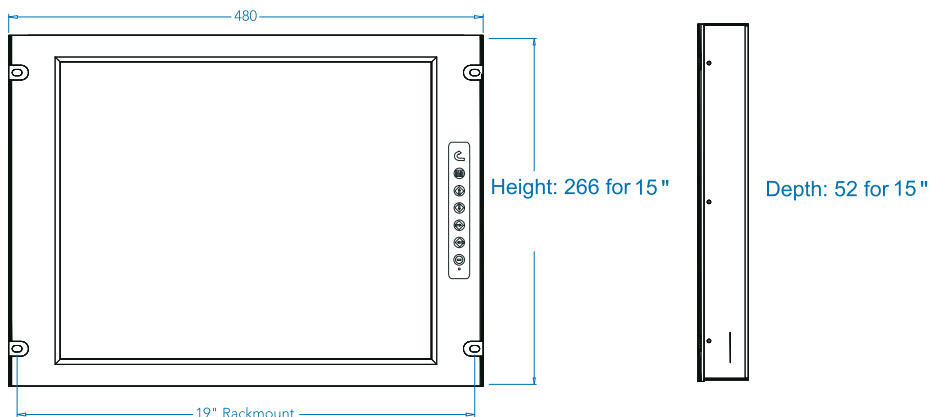

## Options:



AV  
Input



DVI  
Input



BNC  
Input



DC Power  
Input



Touch  
Screen



NEMA 4  
IP65

## Designed for:



## Diagram

Unit : mm

## Display Features & Options

- 6U LCD display with 15" panel
- Multi lingual on screen display menu
- Touchscreen options
- NEMA 4 and IP65 options
- AV Composite Video, S-Video, DVI and BNC input options
- 12, 24 and 48 volt DC power options

## LCD Display Benefits

- ▶ Wide range of applications including industrial control & CCTV security
- ▶ Stylish 6mm cast aluminium front panel

## Monitor

Grade A industrial TFT LCD panel

- 15" 1024 x 768 LCD with 250 nit brightness and 700:1 contrast ratio typical

## Ordering Information

6U 15" LCD

Model	LCDR6U15-01		
-------	-------------	--	--

## Dimensions

Model	Product Dimension (W x D x H)	Net Weight
LCDR6U15-01	480 x 52 x 266 mm 18.9 x 2 x 10.5 inch	6 kg / 13 lbs