


RM1104-C Motherboard Spec

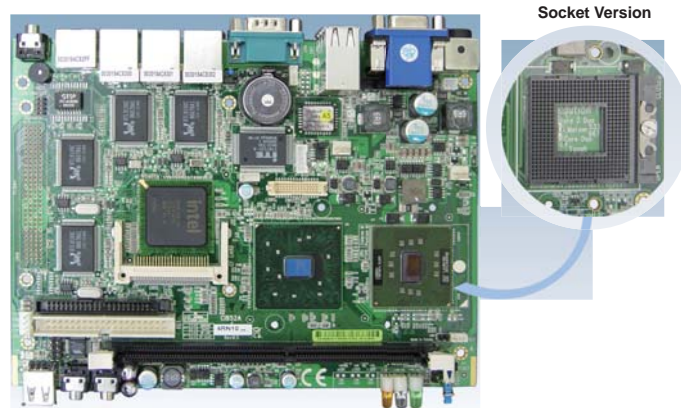

Specifications

| | |
|-----------------------|--|
| . CPU type | Intel Celeron M 1GHz L2 0k CPU |
| . Front Side Bus | 400 / 533 MHz |
| . MB Chipset | Intel 82852 GM / 82852 GME + ICH4 |
| . BIOS | Award BIOS |
| . Graphics | Integrated with Intel 82852 GM / GME Shared system memory up to 64 MB |
| . LVDS | Data format of 18 bits / 36 bits |
| . Memory | 1 x DDR SDRAM DIMM slot (max. 1GB) |
| . IDE | Ultra ATA 100/66/33, 1 x 40 pin 2.54mm, 1 x 44 pin 2.0mm CF Card Type II socket for ATA interface |
| . Audio | AC-Link for Audio CODEC, AC'97 2.1 Support Line-out / Mic-in / Line-in |
| . LAN | 4 x Intel 82541PI 10 / 100 / 1000 Mbps |
| . IO Function | 1 x RS232 IrDA 1.0 / ASKIR protocol, PS/2 keyboard & mouse |
| . USB | 6 x USB 2.0 (4 external + 2 internal) |
| . DIO & WDT (option) | Hardware digital Input & Output, 4 x DI / 4 x DO Hardware Watch Dog Timer, 0~255 sec programmable |
| . Expansion interface | 1 x Mini PCI socket 1 x PCI 104 (option) |
| . Power | On board DC +12V \pm 5% convert to +3.3V / +5V / +12V for system |
| . Dimension | 200 x 150 mm |
| . Operation Temp. | 0 ~ 60 °C |
| . Operation Humidity | 5~95% @ 60 °C, non-condensing |

Back Panel

