



Features

- 2U flip-down foldable triple 17.3 inch widescreen LCD display Drawer
- Triple DVI & VGA Port
- 1920 x 1080 high resolution
- Support FHD with 1080p resolution.
- Build in 2x 2 watts speakers
- Independent front osd control buttons to optimized display
- Adjust angle 0°~90°

Options

- Composite video input
- HDMI or Display port input
- 3G / HD / SD-SDI broadcast grade input
- DC 9~36 V power input
- AR Hardness glass
- Touch screen

LCD Characteristics :

Screen Size	Triple 17.3
Backlight Type	LED
Resolution	1920*1080
Contrast Ratio	400:1
Brightness (cd/m2)	300
View Angles (H/V)	140/120
Pixel Size (HxV) mm	0.1989x0.1989
Max. Color	262K

Input Signals:

DVI-D	Triple DVI-D 24Pin Connector (Female)
VGA	Triple D-SUB 15Pin Connector (Female)
Audio	1 x 3.5" Jack
Power Input	Standard IEC Inlet
Touch-USB (option)	Triple USB A Type connector
Touch-RS232 (option)	Triple D-SUB 9P connector (Female)

Power Specifications :


AC Power Input	Standard IEC Type Power Cord with Internal Power adapter, 100-240V AC Input
Wide Range DC Power Input (option)	Screw Type Terminal Block with internal wide Range DC 9-36V power module

User Controls Interface:

Power ON / OFF via Front Button
Power Mode Status LED indicator
OSD (On Screen Display) Buttons

Mechanical and Environment:

Height	2U Foldable
Rack Depth	550 to 950mm (cabinet front rail to rear rail)
Construction	Metal Housing
Operating Temperature	0 - 50 deg. C
Operating Humidity	5% - 95% (non -condensing)
Anti-Vibration	5 - 500 Hz / 1 Grms PTP
Anti-Shock	15G / Peak (11 ms)
Physical Dimension (WxHxD)	443 x 88 x 580 (mm)
Net Weight	18.5 (KGs)
Certification and Approvals	CE / FCC / RoHS

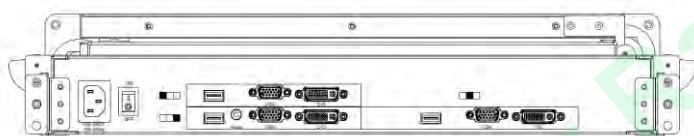

Rear of LCD2U17-3H-015

